


开口式双边切割型固定环 标准型



■标准型



类型	M 材质	S 表面处理	A 附件
SCABD	一般结构用钢	四氧化三铁保护膜	1个内六角螺栓
SCAED		无电解镀镍	1个内六角螺栓(不锈钢)
SCAND	不锈钢	-	

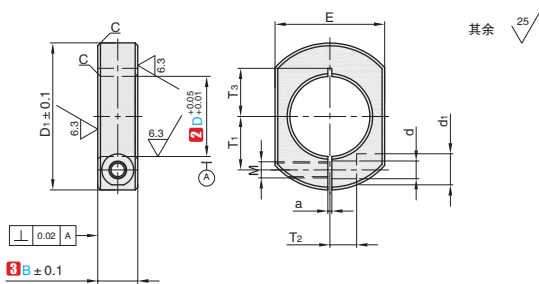

订购编号示例

① 代号	-	② D	-	③ B
SCABD	-	D12	-	B10

① 代号	主要尺寸												
	内径 ② D	③ B	D ₁	E	M(粗牙)	d	d ₁	a	C	T ₁	T ₂	T ₃	
SCABD SCAED SCAND	6	8	20	17	M3	3.4	6	1	0.5	6	4	6~6.5	
		10			M4	4.5	7.5						
	8	8	25	19	M3	3.4	6			8	5	7~9	
		10			M4	4.5	7.5						
	10	8	30	22	M3	3.4	6			9	8~10		
		10			M4	4.5	7.5						
	12	12	34	24	M5	5.5	9			10	9~10		
		10			M4	4.5	7.5						
	15	12	35	24	M5	5.5	9			11.5	6	10~11	
		10											11~13
	16	12	40	30	M5	5.5	9			12	7	11~12	
		10											13
	20	12	40	30	M6	6.6	12			14	7	13	
		15											
	25	12	45	36	M5	5.5	9			15	8	13~15	
		15											17
30	12	50	36	M5	5.5	9	17	7	16				
	15									18	10	16~18	
35	15	55	41	M6	6.6	12	18	10	18~20				
	15									20			
40	15	60	46	M6	6.6	12	23	12	21				
	18									26	13	23	

A3
固定环