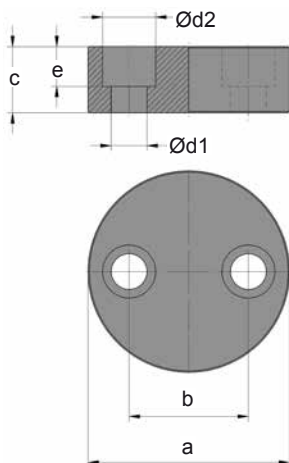


STRIKER PLATES


Accessories

AZOL
GAS


SPFO

WDX35-80-3576


ORDER	Ø d _{max}	a (mm)	b (mm)	c (mm)	Ød1 (mm)	Ød2 (mm)	e (mm)
SPFO 001	25	76	45	25	13.5	20	15
SPFO 002	25	76	45	28	13.5	20	18
SPFO 003	25	76	45	31	13.5	20	21
SPFO 004	25	76	45	34	13.5	20	24
SPFO 005	25	76	45	37	13.5	20	27
SPFO 006	25	76	45	40	13.5	20	30

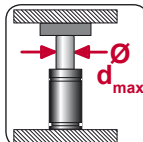

SPFO

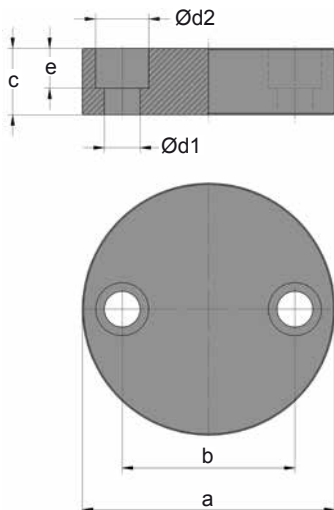WDX35-80-3595


ORDER	Ø d _{max}	a (mm)	b (mm)	c (mm)	Ød1 (mm)	Ød2 (mm)	e (mm)
SPFO 010	45	95	65	25	13.5	20	15
SPFO 011	45	95	65	28	13.5	20	18
SPFO 012	45	95	65	31	13.5	20	21
SPFO 013	45	95	65	34	13.5	20	24
SPFO 014	45	95	65	37	13.5	20	27
SPFO 015	45	95	65	40	13.5	20	30

