



# Headed dowels

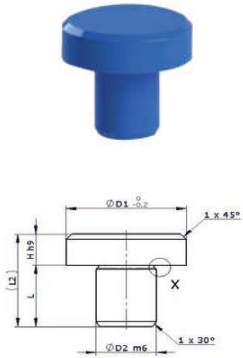

Ø D1	H	Ø D2 mm	L mm	L2 mm	PU	Item No.
6	2.5	4	6.5	9	25	8228-K-60300
6	4.5	4	8.5	13	25	8228-K-60301
6	5	4	6	11	25	8228-K-60302
10	4	6	8.5	13	25	8228-K-60303
10	8	6	8.5	16.5	25	8228-K-60304
12	6	6	10	16	25	8228-K-72878
12	10	6	10	20	25	8228-K-72879
16	5	8	10	15	25	8228-K-60305
16	13	8	10	23	25	8228-K-60306
19.4	6	10	12	18	25	8228-K-60307
19.4	12	10	12	24	25	8228-K-60308
25	8	12	14	22	25	8228-K-60310
25	20	12	14	34	25	8228-K-60311
25	30	12	14	44	25	8228-K-60318
30	25	16	20	45	25	8228-K-60319
30	40	16	20	60	25	8228-K-60320
30	50	16	20	70	25	8228-K-60321
30	65	16	20	85	25	8228-K-60322

## Application example

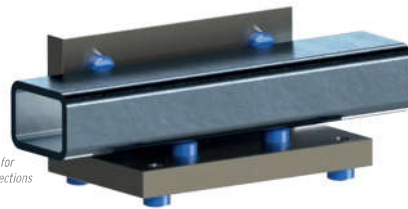

Ceramic headed dowels for wear-free guidance of sections / profiles

