



Spreiz-Blindniet ARCO®

Serie 10.710

 



Aluminium / Stahl



EN AW - 5019 [AlMg5]

- > Flachkopf
- > offen

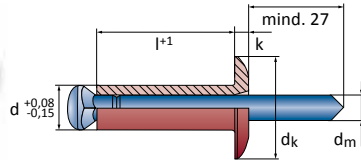

d	l +1		Nr.		
3,2	10,0	1,5 - 5,0	10.710.032.100	500	
	16,0	4,0 - 11,0	10.710.032.160	500	
	18,0	5,0 - 13,0	10.710.032.180	500	
d_k 6,5	d_m 1,7	k 0,8	3,55 +0,1 mm	850 N	720 N
4,0	10,0	1,5 - 5,0	10.710.040.100	500	
	16,0	4,0 - 11,0	10.710.040.160	500	
	18,0	5,0 - 13,0	10.710.040.180	500	
d_k 9,0	d_m 2,4	k 1,5	4,35 +0,1 mm	1330 N	1300 N

d	l +1		Nr.		
4,8	10,0	1,5 - 4,0	10.710.048.100	500	
	15,0	3,0 - 9,0	10.710.048.150	500	
	21,0	8,0 - 15,0	10.710.048.210	500	
	26,0	14,0 - 20,0	10.710.048.260	250	
	35,0	19,0 - 28,0	10.710.048.350	250	
d_k 11,0	d_m 2,8	k 1,5	5,15 +0,1 mm	2100 N	1950 N