



Sealed Blind Rivet CERTO®


Series 10.906

Copper / Stainless Steel A2/A3



[2.0040]

> Dome Head
> closed

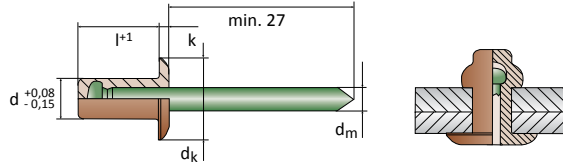

d	l +1	$\frac{+}{-}$	No.	
3,2	6,5	0,5 - 2,0	10.906.032.065	500
	8,0	1,5 - 3,5	10.906.032.080	500
	9,5	3,0 - 5,0	10.906.032.095	500
	12,5	4,5 - 8,0	10.906.032.125	500
d_k 6,0 ± 0,3	d_m 1,7	k 1,1 ± 0,15	3,3 mm 950 N 1250 N	

d	l +1	$\frac{+}{-}$	No.	
4,0	8,0	0,5 - 3,5	10.906.040.080	500
	10,0	3,0 - 5,0	10.906.040.100	500
d_k 8,0 ± 0,4	d_m 2,2	k 1,3 ± 0,2	4,1 mm 1400 N 2100 N	
4,8	9,5	1,0 - 5,0	10.906.048.095	500
	11,5	4,5 - 6,5	10.906.048.115	500
d_k 9,5 ± 0,4	d_m 2,7	k 1,5 ± 0,2	4,9 mm 2150 N 3200 N	