

手柄 摇动手柄、旋转手柄


旋钮 蘑菇头旋钮

code
5天发货

选型指南

举例	型号		型号	
	Code	d	Code	M
标准	SBKDA	10	KRA	10

■ 摇动手柄

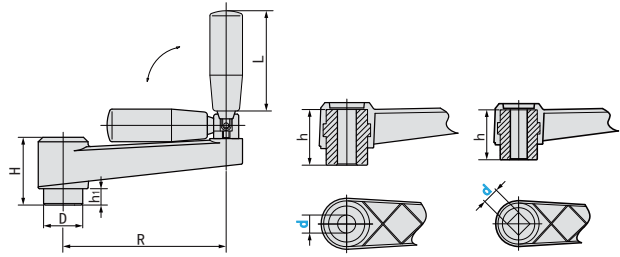


注：可折叠

◆材质：胶木

型号		R	D	A	h	h1	H	L
Code	d							
SBKDA (圆孔)	10	80	22	105	33	10	36	50
SBKDA (圆孔)	12	100	24	129	36	10	40	63
SBKDB (方孔)	14	125	30	160	42	12	45	63
SBKDB (方孔)	16	160	34	195	50	15	55	80

■ 旋转手柄

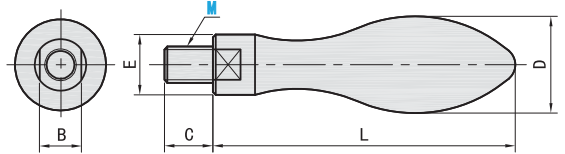


※材质：钢 表面处理：镀铬

型号		L	D	C	E	B
Code	M					
KRA	8	86	23	13	17	14
	10	86	23	13	17	14
	12	86	23	13	17	14

■ 旋钮-蘑菇头




XNEB 内螺纹型

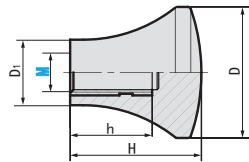

◆材质：胶木

型号		H	D	D1	h
Code	M				
XNEB (内螺纹)	5	16	16	10	10
	6	20	20	12	12
	8	25	25	16	16
	10	32	32	20	20
	12	40	40	25	25

XNEC 外螺纹型

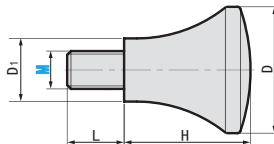

◆材质：胶木

型号		H	L	D	D1
Code	M				
XNEC (外螺纹)	5	16	6	16	10
	6	20	10	20	12
	8	25	15	25	16
	10	32	15	32	20
	12	40	18	40	20