

# Tangential fans for 482.6 mm (19")



Climate control accessories Page 369

**Supply includes:**


- Fully wired unit ready for connection
- Filter mat

**Approvals:**

Available on the Internet

**Technical details:**

Available on the Internet

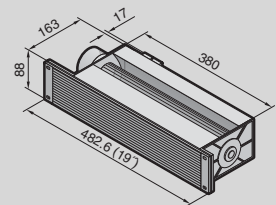

## Air throughput 320 m<sup>3</sup>/h

Model No.	Packs of	3144.000	3145.000	Page
Rated operating voltage V, ~, Hz		230, 1~, 50/60	115, 1~, 50/60	
<b>Air throughput, unimpeded air flow m<sup>3</sup>/h</b>		<b>320</b>	<b>320</b>	
Rated current A		0.16	0.32	
Power consumption W		37	37	
Width mm		482.6	482.6	
Height mm		88	88	
Depth mm		158	158	
Operating temperature range		-10°C...+55°C	-10°C...+55°C	
Noise level dB(A)		52	52	
Speed rpm		2245	2245	
Maximum static pressure difference Pa		65 - 70	65 - 70	

**Accessories**

Digital enclosure internal temperature display and thermostat	1 pc(s).	3114.200	3114.200	379
Enclosure internal thermostat	1 pc(s).	3110.000	3110.000	379
Filter mats	5 pc(s).	3177.000	3177.000	369
Front outlet grille 2 U	1 pc(s).	3176.000	3176.000	372
Roof-mounted fan, roof vent	1 pc(s).	3148.007	3148.007	325
Speed control	1 pc(s).	3120.200	3120.200	381