
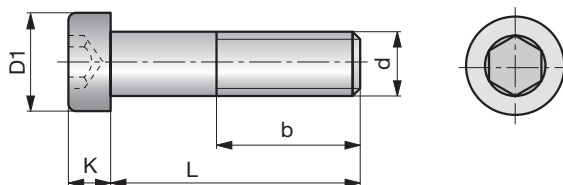


Zylinderkopfschrauben

Cylinder head cap screws

Vis 6 pans creux

2

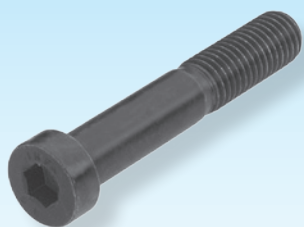

SN3540-

DIN 7984 - 8.8

 SN3540-d-L



d	L	b	D1	K	d	L	b	D1	K
M3	10	8,5	5,5	2	M8	45	22,0	13,0	5,0
	16	14,5	5,5	2		50	22,0	13,0	5,0
M4	10	7,9	7,0	2,8		55	22,0	13,0	5,0
	16	13,9	7,0	2,8	60	22,0	13,0	5,0	
M5	10	7,6	8,5	3,5	M10	16	11,5	16,0	6,0
	12	9,6	8,5	3,5		20	15,5	16,0	6,0
	14	11,6	8,5	3,5		25	20,5	16,0	6,0
	16	13,6	8,5	3,5		30	25,5	16,0	6,0
	20	17,6	8,5	3,5		35	30,5	16,0	6,0
	25	22,6	8,5	3,5	40	26,0	16,0	6,0	
	30	16,0	8,5	3,5	45	26,0	16,0	6,0	
M6	10	7,0	10,0	4,0	50	26,0	16,0	6,0	
	12	9,0	10,0	4,0	55	26,0	16,0	6,0	
	14	11,0	10,0	4,0	60	26,0	16,0	6,0	
	16	13,0	10,0	4,0	70	26,0	16,0	6,0	
	20	17,0	10,0	4,0	M12	20	14,8	18,0	7,0
	25	22,0	10,0	4,0		25	19,8	18,0	7,0
	30	18,0	10,0	4,0		30	24,8	18,0	7,0
35	18,0	10,0	4,0	35		29,8	18,0	7,0	
40	18,0	10,0	4,0	40		34,8	18,0	7,0	
M8	16	12,3	13,0	5,0	45	39,8	18,0	7,0	
	20	16,3	13,0	5,0	50	30,0	18,0	7,0	
	25	21,3	13,0	5,0	55	30,0	18,0	7,0	
	30	26,3	13,0	5,0	60	30,0	18,0	7,0	
	35	22,0	13,0	5,0	70	30,0	18,0	7,0	
	40	22,0	13,0	5,0	80	30,0	18,0	7,0	