


Adjustable stud couplings

Male connector

Component parts
Tube socket pre-assembled

Cutting ring connection
at tube end

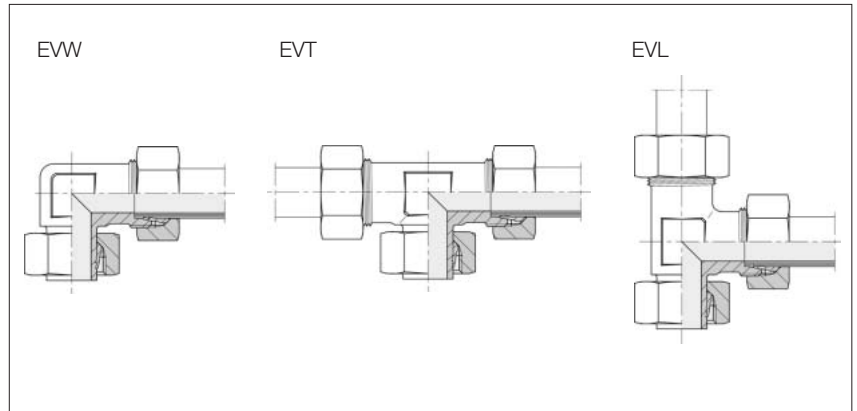

Series Tube OD d1	Pressure	kg/100 approx.	Order No. EWW*	kg/100 approx.	Order No. EVT*	kg/100 approx.	Order No. EVL*
L 6	PN 315	3.9	0 1 58 02 20 07**	5.9	0 1 60 02 20 07**	5.7	0 1 62 02 20 07**
L 8	PN 315	5.5	0 1 58 07 20 07	8.2	0 1 60 07 20 07	8.1	0 1 62 07 20 07
L 10	PN 315	7.0	0 1 58 12 20 07	10.2	0 1 60 12 20 07	10.3	0 1 62 12 20 07
L 12	PN 315	9.6	0 1 58 17 20 07	13.9	0 1 60 17 20 07	13.6	0 1 62 17 20 07
L 15	PN 315	16.4	0 1 58 22 20 07	23.7	0 1 60 22 20 07	23.2	0 1 62 22 20 07
L 18	PN 315	24.2	0 1 58 27 20 07	34.7	0 1 60 27 20 07	34.8	0 1 62 27 20 07
L 22	PN 160	32.9	0 1 58 32 20 07	45.4	0 1 60 32 20 07	45.4	0 1 62 32 20 07
L 28	PN 160	45.0	0 1 58 37 20 07	59.2	0 1 60 37 20 07	59.5	0 1 62 37 20 07
L 35	PN 160	71.4	0 1 58 42 20 07	96.1	0 1 60 42 20 07	95.5	0 1 62 42 20 07
L 42	PN 160	111.7	0 1 58 47 20 07	147.4	0 1 60 47 20 07	147.1	0 1 62 47 20 07
S 6	PN 630	6.4	0 1 58 52 20 07	9.6	0 1 60 52 20 07	9.5	0 1 62 52 20 07
S 8	PN 630	8.2	0 1 58 57 20 07	12.1	0 1 60 57 20 07	12.2	0 1 62 57 20 07
S 10	PN 630	11.7	0 1 58 62 20 07	17.2	0 1 60 62 20 07	17.1	0 1 62 62 20 07
S 12	PN 630	14.6	0 1 58 67 20 07	20.9	0 1 60 67 20 07	21.0	0 1 62 67 20 07
S 14	PN 630	20.3	0 1 58 72 20 07	29.2	0 1 60 72 20 07	29.1	0 1 62 72 20 07
S 16	PN 400	26.9	0 1 58 77 20 07	38.5	0 1 60 77 20 07	37.4	0 1 62 77 20 07
S 20	PN 400	40.4	0 1 58 82 20 07	58.1	0 1 60 82 20 07	57.8	0 1 62 82 20 07
S 25	PN 400	76.7	0 1 58 87 20 07	105.6	0 1 60 87 20 07	105.3	0 1 62 87 20 07
S 30	PN 400	99.9	0 1 58 92 20 07	137.5	0 1 60 92 20 07	136.4	0 1 62 92 20 07
S 38	PN 315	154.5	0 1 58 97 20 07	208.9	0 1 60 97 20 07	208.7	0 1 62 97 20 07

* With union nut and 2S cutting ring

** Sample product code, see:
EWW06L
EVT06L
EVL06L