

V block 120°

standard version

Nr.	A(AF)	max. \emptyset	
21988	16	110	78
21987	25	170	299
21277	40	275	1.218
28175	50	345	2.395




with hard metal surface

Nr.	A(AF)	max. \emptyset	
80976	25	170	382
81512	40	275	1.577
82786	50	345	2.350



with magnetic surface

Nr.	A(AF)	max. \emptyset	
81509	25	170	316
81514	40	275	1.577
82787	50	345	2350

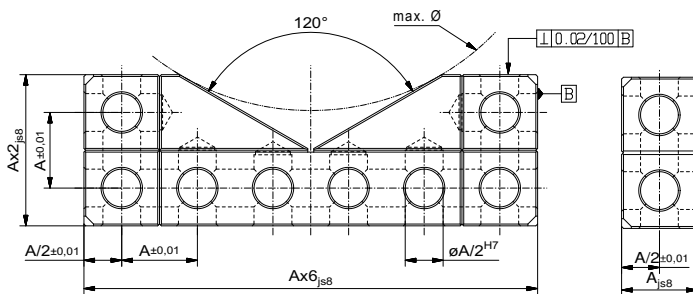

ALUFIX CLASSIC Alufix Classic elements can be anodized in different colours. The colour natural is standard, black (-1) is available as an alternative. Other colours on request.

Surface of V blocks also available with polymer insert (POM, black) on request