
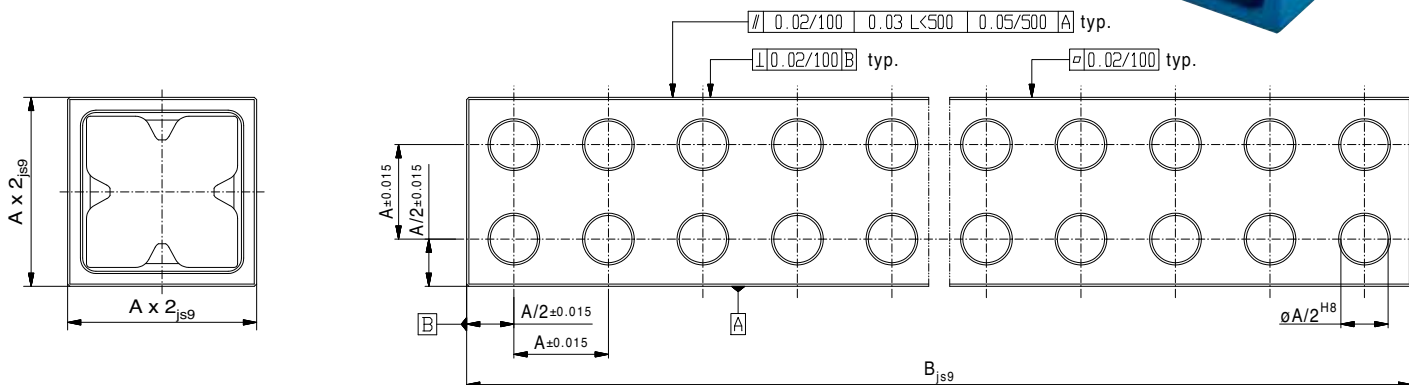


Light bars two row

ALUFIX ECO Light bars are suitable for medium to large fixtures as basic frame material and also for connections direct to the workpiece.

They can be connected using the bores on all 4 sides with quick

or screw connectors, ECO couplings (page 196/197) are used for the face ends.

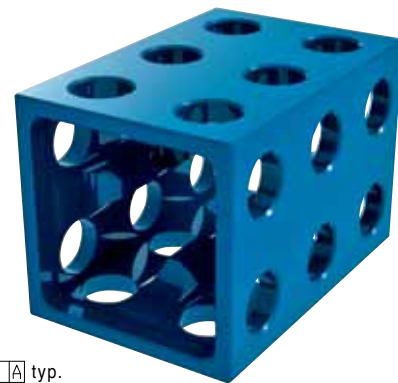

AF25 ECO

A=25, 50 x 50

AF40 ECO

A=40, 80 x 80

AF50 ECO

A=50, 100 x 100

Nr.	B	g
26617-E	50	0.12
25375-E	100	0.24
20426-E	150	0.373
20427-E	200	0.48
22949-E	250	0.60
20254-E	300	0.72
24246-E	350	0.84
20256-E	400	0.96
24248-E	450	1.08
22950-E	500	1.20
24250-E	600	1.44
24251-E	700	1.68
28353-E	800	1.92
24319-E	900	2.16
22951-E	1000	2.4
25025-E	1200	2.9
27915-E	1400	3.4
22952-E	1500	3.6
21226-E	2000	4.8

Nr.	B	g
24393-E	80	480
24940-E	120	720
23937-E	160	810
23938-E	200	1.200
24392-E	240	1.500
24641-E	320	1.900
24809-E	360	2.200
23559-E	400	2.400
24390-E	480	2.900
24451-E	600	3.600
23560-E	800	4.800
24624-E	1000	6.000
23561-E	1200	7.200
23562-E	1600	9.600
23563-E	2000	12.000
23564-E	2400	14.400
25034-E	3000	18.000
23567-E	3600	21.600
23568-E	4000	24.000
23570-E	4800	28.800

Nr.	B	g
27569-E	100	900
28122-E	150	1.300
26735-E	200	1.700
27504-E	250	2.100
26821-E	300	2.600
26786-E	400	3.400
26787-E	500	4.300
26788-E	600	5.200
27505-E	800	6.900
26957-E	1000	8.600
27920-E	1200	10.300
26959-E	1500	12.900
26961-E	2000	17.200
26965-E	3000	25.800
26969-E	4000	34.400
26973-E	5000	43.000
26977-E	6000	51.600



ALUFIX ECO elements can be anodized in different colours. The colour natural (-E) is standard, blue (-E2) is available as an alternative. Black (-E1) and other colours on request

Other dimensions on request